


Vout setting by trimmer and JP2/JP3

JP2	JP3	V(OUT) set range
Short	Open	1.2V - 5.4V
Open	Short	4.9V - 15.5V

Optional thermal management (not assembled)

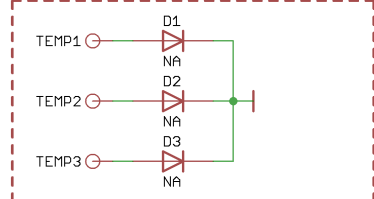

SCH Revision History:  
0 Initial version

**onsemi** TIT: NCP737/740, NCV8737/8740  
MSOP-8 DEMO BOARD 2L

DOC: NCP737ADNADJR2GEVB

BRD: RA0902DB

DATE: 29.05.2025 9:15:44

Rev: 0

Sheet: 1/1